


Fibre-optic cable SOOC-DS-Q-2-R25

Part number: 552811
Product to be discontinued

FESTO

Suitable for SOE4 fibre-optic units.

Type to be discontinued. Available until 2022. See Support Portal for alternative products.

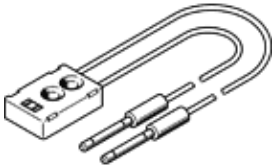

Data sheet

Feature	Value
Materials note	Conforms to RoHS
Measurement method	Fix-focus
Minimal object diameter	0.1 mm
Fibre-optic cable - special feature	Fix-focus
Working range	2 ... 10 mm
Ambient temperature	-55 ... 70 °C
Size, head	Rectangle 13x19,6x5 mm
Fibre optic cable length	2 m
Min. bending radius	25 mm
Outside diameter	2.2 mm
Material housing	ABS
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364 zone III