


# fibre-optic cable SOOC-TB-M4-1-R25-S4

Part number: 552815

FESTO

Suitable for SOE4 fibre-optic units.

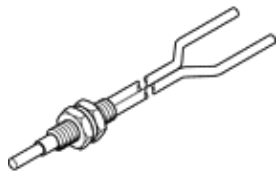

## Data sheet

Feature	Value
Materials note	Contains PWIS substances
Measurement method	Through-beam sensor
Minimal object diameter	0.35 mm
Fibre-optic cable - special feature	Standard
Working range	400 mm
Ambient temperature	-55 ... 70 °C
Size, head	M4
Fibre optic cable length	1 m
Sleeve length	40 mm
Min. bending radius	25 mm
Max. tightening torque	2 Nm
Outside diameter	2.2 mm
Material housing	High alloy steel, non-corrosive
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress