


# Fibre-optic cable SOOC-TB-P-C5-2-R10

Part number: 552828

FESTO

Suitable for SOE4 fibre-optic units.

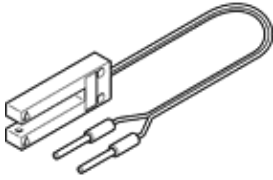

## Data sheet

Feature	Value
Materials note	Conforms to RoHS
Measurement method	Fork light barrier
Minimal object diameter	0.2 mm
Fibre-optic cable - special feature	Fork light barrier
Working range	5 mm
Ambient temperature	-55 ... 70 °C
Size, head	Rectangle 41x15x7 mm Fork pit 5x29 mm
Fibre optic cable length	2 m
Min. bending radius	10 mm
Outside diameter	1.25 mm
Material housing	ABS
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364 zone III