


# plastic tubing PAN

Part number: 553610

FESTO

Please observe the minimum order quantity.

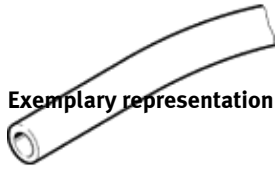

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Outside diameter	4 ... 16 mm
Inside diameter	2.5 ... 12 mm
Conforms to standard	DIN 73378-PA12-PHL
Temperature dependent operating pressure	-0.95 ... 35 bar
Authorisation	TÜV
Certificate issuing department	B 013277 0506 00
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Mineral oil
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-60 ... 100 °C
Colour	blue brown yellow green neutral Red Black silver white
Materials note	Conforms to RoHS
Material tubing	Polyamide 12 TPE-A