


# electrical interface CECX-C-ET

Part number: 553856

FESTO

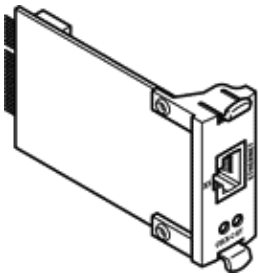

## Data sheet

Feature	Value
Corrosion resistance classification CRC	0 - No corrosion stress
Authorisation	c UL us - Listed (OL)
Materials note	Contains PWIS substances Conforms to RoHS
Power consumption at system bus	0.5 W
Ambient temperature	5 ... 55 °C
Storage temperature	-40 ... 70 °C
Relative air humidity	10 - 95 %
Safety class	III
Product weight	23 g
Test for insensitivity to vibration	EN 60068-2-6 FC 5 - 9 Hz 3,5 mm 9 - 150 Hz 1g
Test for insensitivity to shock	EN 60068-2-27 EA 15 g, 11 ms (half sine)
Status displays	LED yellow = transmit/receive LED green = link
Ethernet, connector plug	8-pin
Ethernet, data transmission speed	10/100 Mbit/s
Ethernet, supported protocols	TCP/IP, EasyIP, Modbus TCP