


connecting cable

NEBC-S1G15-K-2.5-N-B-S1G9

Part number: 553949

FESTO

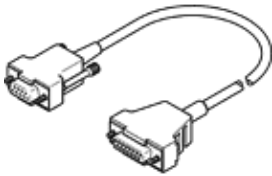

Data sheet

Feature	Value
Assembly position	Any
Electrical connection	Plug socket Sub-D 9-pin 15-pin
Cable interface	SUB-D 15-pin plug SUB-D 9-pin plug
Cable length	2.5 m
Cable attribute	Standard
Min. cable bending radius	78 mm
Cable diameter	5.2 mm
Cable type	LIYCY
Cable structure	3x0,34 Shielded
Colour code, core insulation	brown Green white
Protection class	IP40
Ambient temperature	-30 ... 80 °C
Ambient temperature with flexible cable installation	-5 ... 70 °C
Corrosion resistance classification CRC	0 - No corrosion stress
Material cable sheath	PVC
Cable sheath colour	Grey
Material housing	Plastic, metallised Metal
Material electrical contact	Gold plated