


# Connecting cable NEBV-H1G2L-P-0.5-LE2

Part number: 554029

FESTO

für Magnetventile MH1, ohne LED.

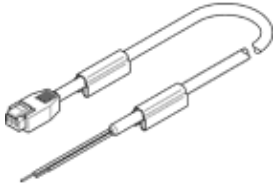

## Data sheet

Feature	Value
Assembly position	Any
Cable attribute	Für statische Anwendungen
Polarity protected	No
Operating status display	Yellow LED
Operating voltage range AC	4.5 ... 26.4 V
Operating voltage range DC	4.5 ... 26.4 V
maximum output current	2,000 mA
Stoßspannungsfestigkeit	0.8 kV
Corrosion resistance classification CRC	4
Protection class	IP40
Ambient temperature	-5 ... 70 °C -20 ... 70 °C
Product weight	12 g
Electrical connection	2-core Straight socket / cable
Cable length	0.5 m
Mounting type	Clip
Colour code, core insulation	Pin 1 = black Pin 3 = schwarz/rot
Materials note	Free of copper and PTFE
Materials information, housing	POM PUR
Materials information, cable sheaths	PVC