


Connecting cable NEBV-H1G2L-P-2.5-LE2

Part number: 554031

FESTO

für Magnetventile MH1, ohne LED.

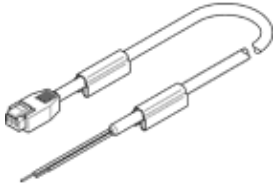

Data sheet

| Feature | Value |
|---|--------------------------------------|
| Assembly position | Any |
| Cable attribute | Für statische Anwendungen |
| Polarity protected | No |
| Operating status display | Yellow LED |
| Operating voltage range AC | 4.5 ... 26.4 V |
| Operating voltage range DC | 4.5 ... 26.4 V |
| maximum output current | 2,000 mA |
| Stoßspannungsfestigkeit | 0.8 kV |
| Corrosion resistance classification CRC | 4 |
| Protection class | IP40 |
| Ambient temperature | -5 ... 70 °C -20 ... 70 °C |
| Product weight | 60 g |
| Electrical connection | 2-core Straight socket / cable |
| Cable length | 2.5 m |
| Mounting type | Clip |
| Colour code, core insulation | Pin 1 = black Pin 3 = schwarz/rot |
| Materials note | Free of copper and PTFE |
| Materials information, housing | POM PUR |
| Materials information, cable sheaths | PVC |