


manifold sub-base VABV-S6-1Q-N12

Part number: 556988

FESTO

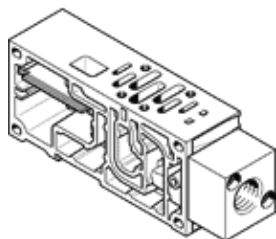

Data sheet

Feature	Value
Width	43 mm
Vibration resistance	Transport application test at severity level 2 in accordance with FN 942017-4 and EN 60068-2-6
Shock resistance	Shock test with severity level 2 in accordance with FN 942017-5 and EN 60068-2-27
Note on forced dynamisation	Switching frequency min. 1/month
CE mark (see declaration of conformity)	to EU directive low-voltage devices
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Product weight	570 g
Pneumatic connection, port 1	1/2 NPT
Materials note	Conforms to RoHS
Material plate	Aluminium die cast