


# coupling

## EAMD-19-15-10-8X10

Part number: 557998

FESTO

drive component, which transmits the rotary motion of a stepper or servo motor

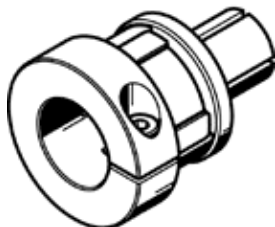

### Data sheet

Feature	Value
Holder diameter 1	10 mm
Holder diameter 2	8 mm
Size	19
Nominal length	15 mm
Assembly position	Any
Max. speed	10,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	0.445 kgmm <sup>2</sup>
Transferable torque	2 Nm
Product weight	13 g
Materials note	Conforms to RoHS