


push-in bulkhead connector NPQM-H-Q10-E-P10

Part number: 558809

FESTO

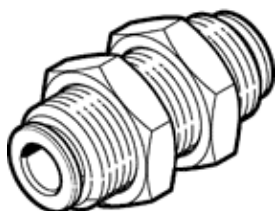

Data sheet

| Feature | Value |
|---|--|
| Size | Standard |
| Nominal size | 9 mm |
| Design | Bulkhead |
| Container size | 10 |
| Design structure | Push/pull principle |
| Operating pressure for entire temperature range | -0.095 ... 1.6 MPa |
| Operating pressure complete temperature range | -0.95 ... 16 bar |
| Operating pressure for entire temperature range | -13.775 ... 232 psi |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -20 ... 70 °C |
| Product weight | 51.5 g |
| Pneumatic connection, port 1 | For tubing outside diameter 10 mm |
| Pneumatic connection, port 2 | For tubing outside diameter 10 mm |
| Materials note | Conforms to RoHS |
| Material housing | Nickel-plated brass |
| Material nut | Nickel-plated brass |
| Material of tubing seal | NBR |