


# Parallel kit EAMM-U-A22-70A

Part number: 559787

FESTO

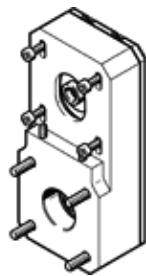

## Data sheet

Feature	Value
Size	22
Assembly position	Any
Max. speed	4,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	10.13 kgmm <sup>2</sup>
No-load driving torque	0.2 Nm
Transferable torque	5.5 Nm
Product weight	540 g
Materials note	Conforms to RoHS