


Axial kit

EAMM-A-A22-55A

Part number: 559799

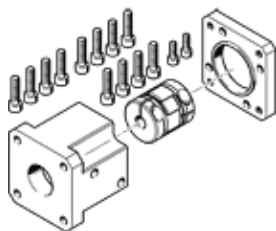

Data sheet

Feature	Value
Size	22
Assembly position	Any
Max. speed	10,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	6.06 kgmm ²
Transferable torque	5.1 Nm
Product weight	430 g
Materials note	Conforms to RoHS