


end plate VABE-S6-2RZ-N34

Part number: 560840

FESTO

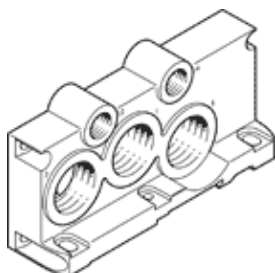

Data sheet

Feature	Value
Based on the standard	ISO 5599-2
Assembly position	Any
Valve terminal type	44
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Product weight	336 g
Pilot air port 12	1/4 NPT
Pilot air port 14	1/4 NPT
Pneumatic connection, port 1	3/4 NPT
Pneumatic connection, port 3	3/4 NPT
Pneumatic connection, port 5	3/4 NPT
Materials note	Conforms to RoHS
Material end plate	Aluminium die cast