 



# end plate VMPAL-EPL-SD25

Part number: 560938

FESTO

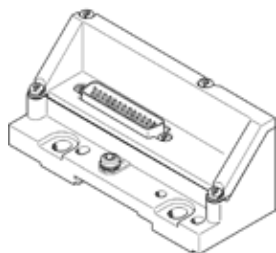

## Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Max. number of valve positions	24
Valve terminal structure	Valve sizes can be mixed
Max. number of solenoid coils	24
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP67
Note on degree of protection	in assembled condition with accessories VMPAL-KM
Ambient temperature	-5 ... 50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin plug
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	25
Materials note	Conforms to RoHS
Material end plate	Aluminium die cast PA-reinforced