


end plate VMPAL-EPL-KL33-IP40

Part number: 560943

FESTO

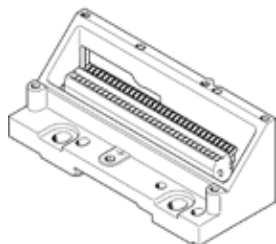

Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Max. number of valve positions	32
Valve terminal structure	Valve sizes can be mixed
Max. number of solenoid coils	32
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP40
Note on degree of protection	in assembled condition
Ambient temperature	-5 ... 50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin plug
Electrical connection 1, connection type	Terminal strip
Electrical connection 1, connection technology	Cage clamp terminal
Electrical connection 1, number of pins/wires	33
Materials note	Conforms to RoHS
Material end plate	Aluminium die cast PA-reinforced