


# end plate VMPAL-EPR-SP

Part number: 560947

FESTO

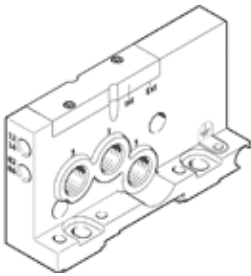

## Data sheet

Feature	Value
Width	28.8 mm
Length	107.3 mm
Integrated function	Pilot air selector for choosing the pilot air supply (internal or external)
Flow direction	reversible
Valve terminal structure	Valve sizes can be mixed
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 IP67
Note on degree of protection	in assembled condition
Ambient temperature	-5 ... 50 °C
Product weight	180 g
Auxiliary pilot air port 12/14	M7
Pilot exhaust port 82/84	M7
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 5	G1/4
Materials note	Conforms to RoHS
Material end plate	Aluminium die cast PA-reinforced