


# power supply module VMPAL-SP-QS10

Part number: 560951

FESTO

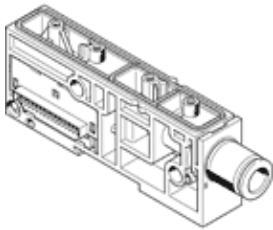

## Data sheet

| Feature                                 | Value                                    |
|---|--|
| Width                                   | 23.2 mm                                  |
| Length                                  | 107.3 mm                                 |
| Integrated function                     | with electrical interlinking module      |
| Valve terminal structure                | Valve sizes can be mixed                 |
| Operating pressure MPa                  | -0.09 ... 1 MPa                          |
| Operating pressure                      | -0.9 ... 10 bar                          |
| Pilot pressure MPa                      | 0.3 ... 0.8 MPa                          |
| Pilot pressure                          | 3 ... 8 bar                              |
| Corrosion resistance classification CRC | 3 - High corrosion stress                |
| PWIS conformity                         | VDMA24364-B1/B2-L                        |
| Ambient temperature                     | -5 ... 50 °C                             |
| Product weight                          | 50 g                                     |
| Pneumatic connection, port 1            | For tubing outside diameter 10 mm        |
| Materials note                          | Conforms to RoHS                         |
| Material supply module                  | Wrought Aluminium alloy<br>PA-reinforced |