


power supply module VMPAL-SP-QS1/2"

Part number: 560954

FESTO

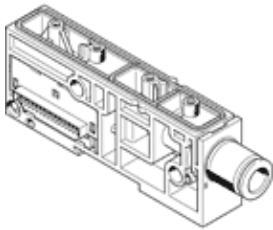

Data sheet

Feature	Value
Width	23.2 mm
Length	107.3 mm
Integrated function	with electrical interlinking module
Valve terminal structure	Valve sizes can be mixed
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	50 g
Pneumatic connection, port 1	for tubing, 1/2" outside diameter
Materials note	Conforms to RoHS
Material supply module	Wrought Aluminium alloy PA-reinforced