


plate
VMPAL-EG-QS3/8"
Part number: 560959

FESTO

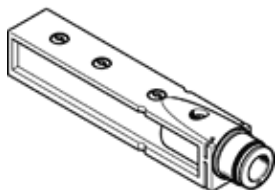

Data sheet

Feature	Value
Width	20.5 mm
Length	107.3 mm
Integrated function	ducted exhaust air
Valve terminal structure	Valve sizes can be mixed
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pressure regulation range	0.5 ... 5 bar
Inlet pressure 1	0.5 ... 10 bar
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	60 g
Pneumatic ports 3/5 combined	for tubing, 3/8" outside diameter
Materials note	Conforms to RoHS
Material plate	PA