

# blanking plug QSPC10


Part number: 562243

Classic - do not use for new projects

FESTO

To seal connections on valves or blanking plates.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

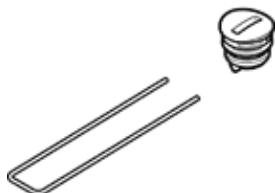

## Data sheet

| Feature   | Value   |
|---|---|
| Size  | Standard  |
| Design  | Straight design   |
| Container size                                  | 10  |
| Operating pressure for entire temperature range | 0 ... 0.8 MPa   |
| Operating pressure complete temperature range   | 0 ... 8 bar   |
| Operating pressure for entire temperature range | 0 ... 116 psi   |
| Operating medium                                | Compressed air in accordance with ISO8573-1:2010 [7::-] |
| Corrosion resistance classification CRC         | 0 - No corrosion stress                                 |
| PWIS conformity                                 | VDMA24364-B1/B2-L                                       |
| Ambient temperature                             | -5 ... 60 °C  |
| Product weight                                  | 0.4 g   |
| Mounting type                                   | Mounting pin  |
| Pneumatic connection, port 1                    | Cartridge 10 mm   |
| Materials note                                  | Conforms to RoHS  |
| Material blanking plug                          | POM   |
| Material o-ring                                 | NBR   |