


sub-base VABS-S7-S-G14

Part number: 563396

FESTO

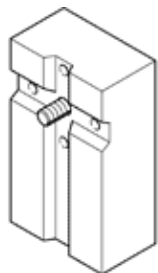

Data sheet

Feature	Value
Assembly position	Any
Operating pressure MPa	0 ... 1 MPa
Operating pressure	0 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Mounting type	with through hole
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	Flange 1/4 NAMUR port pattern
Pneumatic connection, port 3	G1/4
Materials note	Conforms to RoHS
Material seals	NBR
Material plate	Aluminium (Ematal coated)