


barbed hose fitting N-3/4-P-19-NPT

Part number: 564848

FESTO

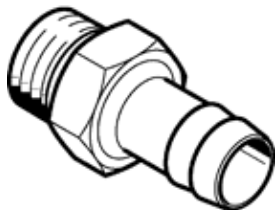

Data sheet

Feature	Value
Nominal size	16.5 mm
Type of seal on screw-in stud	coating
Assembly position	Any
Design	Straight design
Container size	1
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque	40 Nm
Product weight	44 g
Pneumatic connection, port 1	Male thread, 3/4 NPT
Pneumatic connection, port 2	For tubing internal diameter 19 mm
Materials note	Conforms to RoHS
Material housing	Anodised aluminium