


Push-in sleeve QSH-F-6-4

Part number: 564892

FESTO

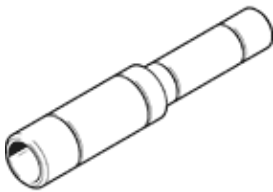

Data sheet

| Feature | Value |
|---|--|
| Size | Standard |
| Nominal size | 2 mm |
| Operating pressure complete temperature range | -0.95 ... 16 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 3 |
| Food safety | to manufacturer's declaration |
| Ambient temperature | 0 ... 150 °C |
| Authorisation | Germanischer Lloyd |
| Product weight | 4.4 g |
| Pneumatic connection, port 1 | Push-in sleeve QS-6 |
| Pneumatic connection, port 2 | Push-in sleeve QS-4 |
| Materials note | Conforms to RoHS |
| Materials information, housing | Brass Chromium and nickel plated |