


electrical connection box VAVE-L1-1H2-LR

Part number: 566716
★ Core product range

FESTO

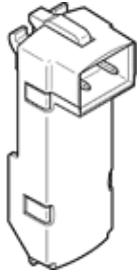

Data sheet

Feature	Value
Polarity protected	for operating voltage
Additional functions	Spark arresting Reduction of holding current
Signal status display	LED
Nominal operating voltage DC	24 V
Surge strength	0.8 kV
Degree of contamination	3
Authorisation	RCM Mark
CE mark (see declaration of conformity)	to EU directive for EMC
UKCA marking (see declaration of conformity)	To UK instructions for EMC
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP40
Ambient temperature	-5 ... 60 °C
Assembly position	Any
Product weight	1.5 g
Electrical connection	2-pin Plug socket
Protective earth connection	Not available
Mounting type	Clip
Housing colour	Black
Materials note	Conforms to RoHS
Material housing	PA