 



# vertical pressure shut-off plate

## VMPA1-HS

Part number: 567805

FESTO

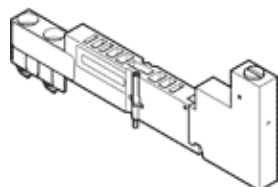

## Data sheet

Feature	Value
Width	10 mm
Assembly position	Any
Pneumatic vertical stacking	Shut-off for 1
Operating pressure	3 ... 8 bar
Standard nominal flow rate ventilation	103 l/min
Standard nominal flow rate venting	213 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65
Ambient temperature	-5 ... 50 °C
Product weight	60 g
Vertical stacking type of mounting	on manifold block on individual sub-base
Materials note	Conforms to RoHS
Material housing	Wrought Aluminium alloy PA-reinforced