


# end plate VMPAL-EPL-CPX

Part number: 570783

FESTO

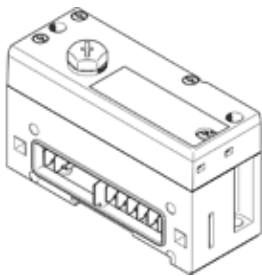

## Data sheet

Feature	Value
Width	40 mm
Length	107.3 mm
Max. number of valve positions	32
Valve terminal structure	Valve sizes can be mixed
Max. number of solenoid coils	32
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP67
Note on degree of protection	in assembled condition
Ambient temperature	-5 ... 50 °C
Product weight	130 g
Electrical connection 1, function	Fieldbus
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	internal for CPX
Materials note	Conforms to RoHS
Material end plate	Aluminium die cast PA-reinforced