


Plastic tubing PAN-M-6X1-GN-500

Part number: 572094

FESTO

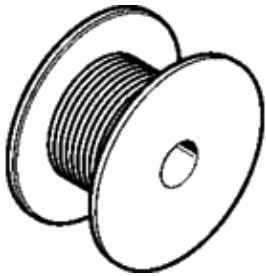

Data sheet

Feature	Value
Outside diameter	6 mm
Bending radius relevant for flow rate	35 mm
Inside diameter	4 mm
Min. bending radius	15 mm
Temperature dependent operating pressure	-0.95 ... 36 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Ambient temperature	-60 ... 100 °C
Product weight according to length	0.016 kg/m
Colour	green
Shore hardness	D 65 +/-3
Materials note	Free of copper and PTFE Conforms to RoHS
Materials information for tubing	Polyamide 12