

cable socket


NEFU-X24F-1-M12G4

Part number: 572227

Product to be discontinued

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

FESTO

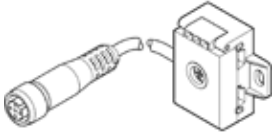

Data sheet

Feature	Value
Width	36 mm
Height	40 mm
Length	40 mm
Mounting type	with through hole
Product weight	60 g
Fieldbus interface	bush, M12x1, 4-pin, A-coded
DC operating voltage, AS interface	26.5 ... 31.6 V
Nominal DC operating voltage, AS interface	26.5 V
DC operating voltage, load voltage	20.4 ... 26.4 V
Nominal DC operating voltage, load voltage	24 V
Protection class	IP65 in assembled condition to IEC 60529
Ambient temperature	-25 ... 75 °C
Storage temperature	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	PA
Material cover	PA