


Fixed restrictor VMPA1-FT-NW0.3-10

Part number: 572544

FESTO

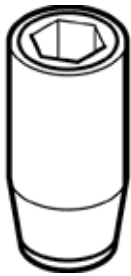

Data sheet

Feature	Value
Valve function	Throttle function
Pneumatic connection, port 1	Sub-base
Mounting type	Threaded
Standard nominal flow rate in flow control direction	3.5 ... 5.5 l/min
Operating pressure	-0.9 ... 10 bar
Ambient temperature	-5 ... 60 °C
Nominal size	0.3 mm
Assembly position	Any
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-20 ... 40 °C
Medium temperature	-5 ... 60 °C
Product weight	0.06 g
Materials note	Conforms to RoHS
Material hollow bolt	Wrought Aluminium alloy