


manifold rail

VABM-L1-10G-G18-5-GR

Part number: 573424

FESTO

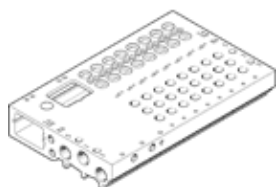

Data sheet

Feature	Value
Grid dimension	10.5 mm
Assembly position	Any
Max. number of valve positions	5
Authorisation	c UL us - Recognized (OL)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-20 ... 60 °C
Product weight	363 g
Auxiliary pilot air port 12/14	M5
Pilot exhaust port 82/84	M5
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 3	G1/8
Pneumatic connection, port 5	G1/8
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminium alloy