


# pneumatic terminal LT-2-PK-4-DA

Part number: 5869

FESTO

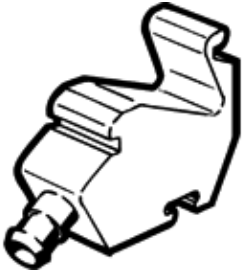

## Data sheet

Feature	Value
Operating pressure	0.1 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-::-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	6 g
Pneumatic connection	Barbed fitting PK-4
Materials note	Conforms to RoHS