 



AND gate ZK-1/8-B

Part number: 6680

FESTO

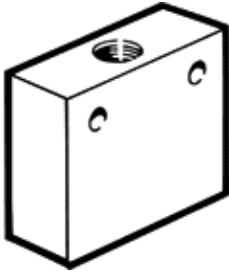

Data sheet

Feature	Value
Valve function	AND function
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Mounting type	with through hole
Standard nominal flow rate	550 l/min
Operating pressure	1 ... 10 bar
Ambient temperature	-10 ... 60 °C
Material housing	Wrought Aluminium alloy Anodised
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Nominal size	4.5 mm
Assembly position	Any
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Product weight	45 g
Pneumatic connection, port 3	G1/8
Materials note	Conforms to RoHS
Material seals	NBR