


multi-socket KDVF-8

Part number: 7563

FESTO

For multiple tube connector for plastic tubing ND 2, 3 and 4 mm.

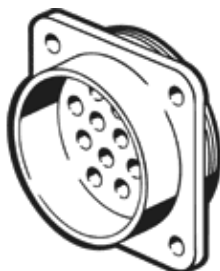

Data sheet

| Feature | Value |
|---|---|
| Nominal size | 4 mm |
| Operating pressure | -0.95 ... 16 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Medium temperature | -10 ... 60 °C |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 36 g |
| Max. number of connections | 8 |
| Pneumatic connection | PK-2 PK-3 PK-4 |
| Colour | Grey |
| Materials note | Conforms to RoHS |