 



vertical pressure supply plate

VABF-S4-2-P1A14-N18

Part number: 8000694

FESTO

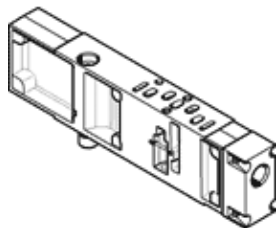

Data sheet

Feature	Value
Width	18 mm
Based on the standard	ISO 15407-2
Assembly position	Any
Pneumatic vertical stacking	Alternative pressure supply for 1 and 14
Operating pressure MPa	1 MPa
Operating pressure	10 bar
Standard nominal flow rate	430 l/min
CE mark (see declaration of conformity)	to EU directive low-voltage devices
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Ambient temperature	-5 ... 50 °C
Product weight	140 g
Vertical stacking type of mounting	on manifold block on individual sub-base
Pneumatic connection, port 1	1/8 NPT
Materials note	Conforms to RoHS
Material housing	Aluminium die cast