


input/output module

CDPX-EA-V2

Part number: 8023321

FESTO

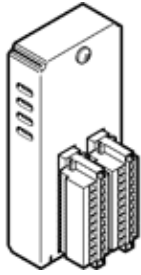

Data sheet

Feature	Value
Depth	34 mm
Height	89 mm
Length	41 mm
Authorisation	C-Tick c UL us - Listed (OL)
CE mark (see declaration of conformity)	to EU directive for EMC in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 70 °C
Relative air humidity	5 - 85 % non-condensing
Protection class	IP20
Ambient temperature	0 ... 50 °C
Product weight	80 g
Materials note	Conforms to RoHS
Digital inputs, number	8
Digital inputs, input signal delay	0,1 ms 3 ms 10 ms 20 ms
Digital inputs, input voltage/current	24 V DC
Digital inputs, nominal value for True	12 - 30 VDC
Digital inputs, nominal value for False	0 V
Digital inputs, electrical isolation	Yes
Digital outputs, number	7
Digital outputs, contact	1 relay
Digital outputs, output voltage	12 - 30 V DC
Digital outputs, output current	0,5 A
Digital outputs, electrical isolation	Yes
Digital outputs, short-circuit proof	Yes
Digital outputs, overload proof	Yes