


flow control VFFG-T-M5-A-V1

Part number: 8025716

FESTO

This type is suitable for vacuum.

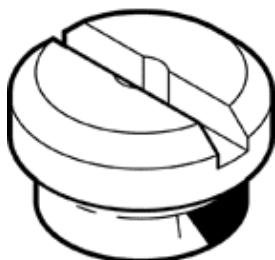

Data sheet

Feature	Value
Valve function	Throttle function
Mounting type	with thread
Operating pressure	-0.9 ... 10 bar
Ambient temperature	-5 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-20 ... 60 °C
Materials note	Conforms to RoHS
Material hollow bolt	PA