


# manifold block

## VABM-B10-25EEE-G12-2

Part number: 8026315

FESTO

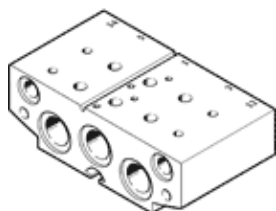

## Data sheet

| Feature                                 | Value                         |
|---|-------------------------------|
| Grid dimension                          | 27.5 mm                       |
| Assembly position                       | Any                           |
| Max. number of valve positions          | 2                             |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity                         | VDMA24364-B1/B2-L             |
| Product weight                          | 258 g                         |
| Mounting type                           | with through hole             |
| Pilot air port 12                       | G1/8                          |
| Pilot air port 14                       | G1/8                          |
| Pneumatic connection, port 1            | G1/2                          |
| Pneumatic connection, port 3            | G1/2                          |
| Pneumatic connection, port 5            | G1/2                          |
| Materials note                          | Conforms to RoHS              |
| Material manifold                       | Wrought Aluminium alloy       |