


supply plate

VABF-B10-30-P1A4-G38

Part number: 8026434

FESTO

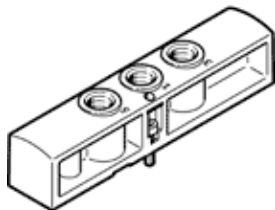

Data sheet

| Feature | Value |
|-----------------------------------------|-------------------------------|
| Operating pressure MPa | -0.09 ... 1 MPa |
| Operating pressure | -0.9 ... 10 bar |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Max. tightening torque | 6 Nm |
| Product weight | 167 g |
| Mounting type | with through hole |
| Pneumatic connection, port 1 | G3/8 |
| Pneumatic connection, port 3 | G3/8 |
| Pneumatic connection, port 5 | G3/8 |
| Materials note | Conforms to RoHS |
| Material supply plate | Aluminium die cast |