 



vertical pressure supply plate VMPA2-VSP-QS3/8

Part number: 8029492

FESTO

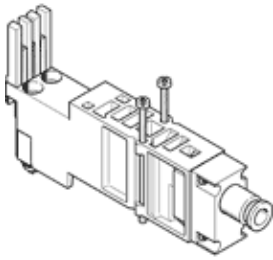

Data sheet

| Feature | Value |
|---|--|
| Grid dimension | 21 mm |
| Operating pressure | -0.9 ... 10 bar |
| Pilot pressure | 3 ... 8 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| Ambient temperature | -5 ... 50 °C |
| Product weight | 90 g |
| Pneumatic connection, port 1 | QS-3/8 |
| Materials note | Conforms to RoHS |
| Material information, supply plate | PA-reinforced |