


**y-fitting**  
**NPFC-Y-R18-2G18-MFF**  
Part number: 8030231

**FESTO**

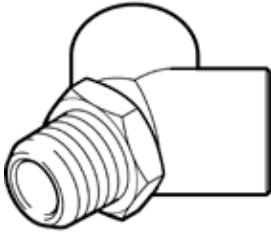

## Data sheet

Feature	Value
Material threaded fitting	Nickel-plated brass
Container size	10
Operating pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:~:]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	30.7 g
Pneumatic connection, port 1	R1/8
Pneumatic connection, port 2	G1/8
Materials note	Conforms to RoHS