


**t-fitting**  
**NPFC-T-2G34-R34-FMF**  
Part number: 8030250

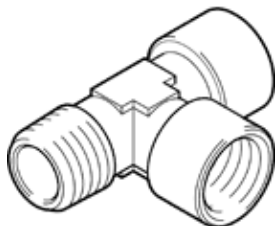

**Data sheet**

Feature	Value
Material threaded fitting	Nickel-plated brass
Container size	10
Operating pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	186 g
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	R3/4
Materials note	Conforms to RoHS