


t-fitting
NPFC-T-G38-2R38-FMM
Part number: 8030257

FESTO

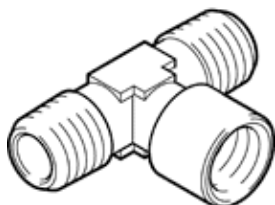

Data sheet

Feature	Value
Material threaded fitting	Nickel-plated brass
Container size	10
Operating pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:--:--]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	60.8 g
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 2	R3/8
Materials note	Conforms to RoHS