


**t-fitting**  
**NPFC-T-2R14-G14-MMF**  
Part number: 8030260

**FESTO**

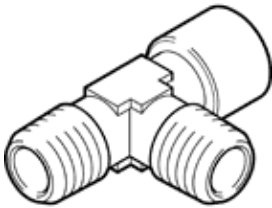

**Data sheet**

<b>Feature</b>	<b>Value</b>
Material threaded fitting	Nickel-plated brass
Container size	10
Operating pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-::-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	40.3 g
Pneumatic connection, port 1	R1/4
Pneumatic connection, port 2	G1/4
Materials note	Conforms to RoHS