


**x-fitting**  
**NPFC-X-4G38-F**  
Part number: 8030263

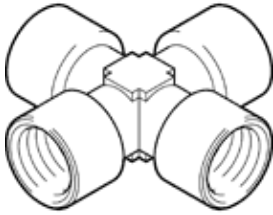

**Data sheet**

| <b>Feature</b>                          | <b>Value</b>                                            |
|-----------------------------------------|---------------------------------------------------------|
| Material threaded fitting               | Nickel-plated brass                                     |
| Container size                          | 10                                                      |
| Operating pressure                      | -0.95 ... 50 bar                                        |
| Operating medium                        | Compressed air in accordance with ISO8573-1:2010 [-:~:] |
| Corrosion resistance classification CRC | 1 - Low corrosion stress                                |
| PWIS conformity                         | VDMA24364-B1/B2-L                                       |
| Ambient temperature                     | -20 ... 150 °C                                          |
| Product weight                          | 100.1 g                                                 |
| Pneumatic connection, port 1            | G3/8                                                    |
| Pneumatic connection, port 2            | G3/8                                                    |
| Materials note                          | Conforms to RoHS                                        |