


# reducing sleeve NPFC-R-G34-G12-F

Part number: 8030297

FESTO

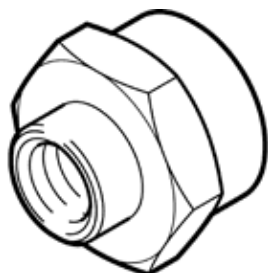

## Data sheet

| Feature                                 | Value   |
|---|---|
| Material threaded fitting               | Nickel-plated brass                                     |
| Container size                          | 10  |
| Operating pressure                      | -0.95 ... 50 bar  |
| Operating medium                        | Compressed air in accordance with ISO8573-1:2010 [-::-] |
| Corrosion resistance classification CRC | 1 - Low corrosion stress                                |
| PWIS conformity                         | VDMA24364-B1/B2-L                                       |
| Ambient temperature                     | -20 ... 150 °C  |
| Product weight                          | 56.2 g  |
| Pneumatic connection, port 1            | G3/4  |
| Pneumatic connection, port 2            | G1/2  |
| Materials note                          | Conforms to RoHS  |