


# non-return valve VMPA14-RV

Part number: 8039820

FESTO

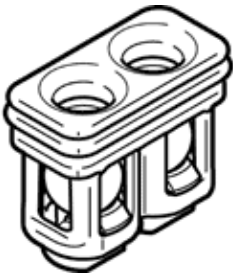

## Data sheet

Feature	Value
Valve function	piloted non-return function
Type of actuation	pneumatic
Mounting type	Clip
Standard nominal flow rate	350 l/min
Operating pressure MPa	0.05 ... 0.8 MPa
Operating pressure	0.5 ... 8 bar
Pilot pressure MPa	0.05 ... 0.8 MPa
Pilot pressure	0.5 ... 8 bar 7.25 ... 116 psi
Ambient temperature	-5 ... 50 °C
Material housing	POM
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Assembly position	Any
Type of actuation, controlled non-return function	pneumatic
Operating pressure complete temperature range	0.5 ... 8 bar
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-20 ... 40 °C
Medium temperature	-5 ... 50 °C
Pilot medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Product weight	0.17 g
Materials note	Conforms to RoHS
Material seals	NBR