


# Cabinet trough feed NEFU-D12G4-R3DW4

Part number: 8040457

FESTO

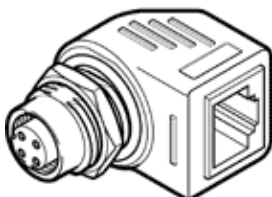

## Data sheet

Feature	Value
Length	40,1 mm
Conforms to standard	EN 61076-2-101 IEC 60603-7-3
Mounting type	Tightened
Electrical connection 1	Straight socket, M12x1, 4-pin, D-coded
Electrical connection 2	Angled socket, RJ45, 4-pin
Operating voltage range DC	0 ... 30 V
Acceptable current load at 40°C	2 A
Surge strength	0.8 kV
Transmission properties	In accordance with category 5, EN 50173, class D In accordance with category 5, ISO/IEC 11801, class D
Protection class	IP20 IP65 IP67
Ambient temperature	-5 ... 60 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	Nickel-plated brass PA Zinc die-casting
Housing colour	Black
Material electrical contact	Brass Gold plated