


Cabinet trough feed NEFU-D12G4-D12DG4

Part number: 8040459

FESTO

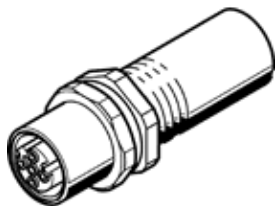

Data sheet

Feature	Value
Conforms to standard	EN 61076-2-101
Mounting type	Tightened
Electrical connection 1	Straight socket, M12x1, 4-pin, D-coded
Electrical connection 2	Straight socket, M12x1, 4-pin, D-coded
Operating voltage range DC	0 ... 30 V
Acceptable current load at 40°C	4 A
Surge strength	0.8 kV
Transmission properties	In accordance with category 5, EN 50173, class D In accordance with category 5, ISO/IEC 11801, class D
Protection class	IP65 IP67
Ambient temperature	-25 ... 85 °C
PWIS conformity	VDMA24364 zone III
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	Nickel-plated brass
Housing colour	silver
Material electrical contact	Brass Gold plated