


non-return valve VABF-L1-10H-H2

Part number: 8047364

FESTO

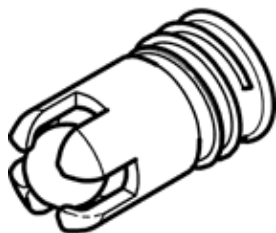

Data sheet

Feature	Value
Valve size	10 mm
Valve function	piloted non-return function
Operating pressure MPa	0.05 ... 0.8 MPa
Operating pressure	0.5 ... 8 bar
Authorisation	c UL us - Recognized (OL)
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 60 °C
Product weight	0.4 g
Mounting type	Tapped
Materials note	Conforms to RoHS